

DEEP HINGED WINDOW KIT

BUL10295



REV. E

ASSEMBLY INSTRUCTIONS FOR DEEP HINGED WINDOW KITS (1481WDH)

INSTRUCTIONS :

- A) Locate window KIT in desired location.
- B) Use window KIT as template for marking mounting hole location.
(Use chart to confirm maximum cutout size)
- C) Mark all holes in body.
- D) Drill (9/32" / 7.1mm) holes.
- E) File sharp edges of cutout.
- F) Install window into place using supplied hardware.
- G) Tighten hardware until the gasket is fully compressed against the mating surface.

ITEM #	DESCRIPTION
1	1481WDH
2	SCREW 1/4-20X3/4 HEX ZP
3	NUT - 1/4-20 UNC, KEPS, ZP

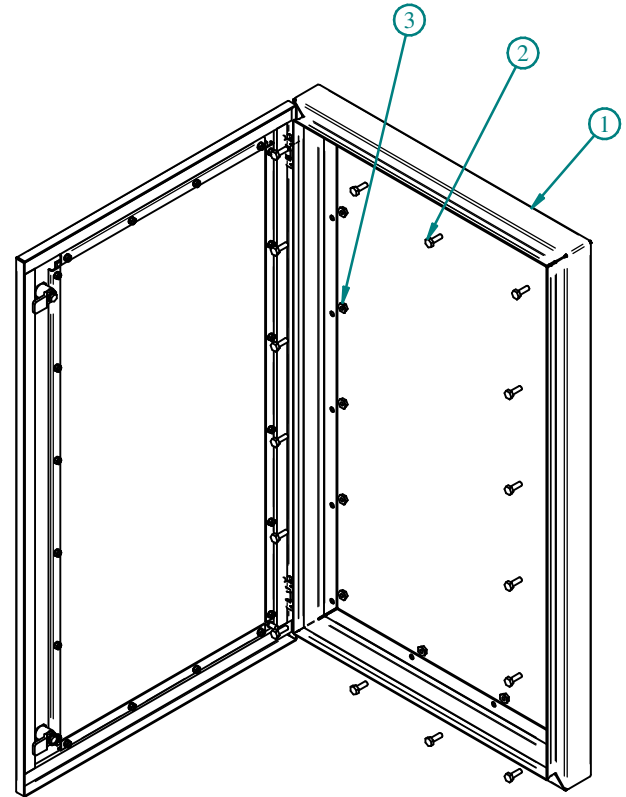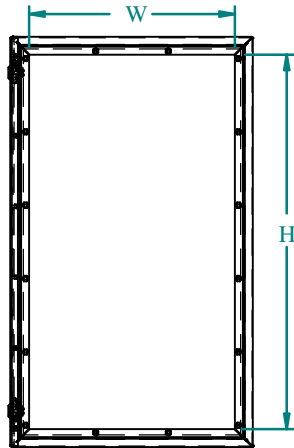

PART NUMBER	MAXIMUM CUT OUT SIZE		NUMBER OF SCREWS
	H	W	
1481WDH1418	9.19	11.56	8
1481WDH1612	11.19	5.14	8
1481WDH2016	15.19	9.14	8
1481WDH2416	19.19	9.14	10
1481WDH2420	19.19	13.14	12
1481WDH3024	25.19	17.14	14
1481WDH2430	19.19	23.14	14
1481WDH3624	31.19	17.14	16
1481WDH1620	11.19	13.14	10
1481WDH1624	17.14	11.19	10
1481WDH2024	17.14	15.19	10

PART SHOWN -

NOTE: ALL PARTS ALSO OFFERED IN STAINLESS STEEL.

