


TABLE A

PART NO	LENGTH
ZL-CO-CBL20	0.5m [1.6 ft]
ZL-CO-CBL20-1	1.0m [3.3 ft]
ZL-CO-CBL11-2	2.0m [6.6 ft]

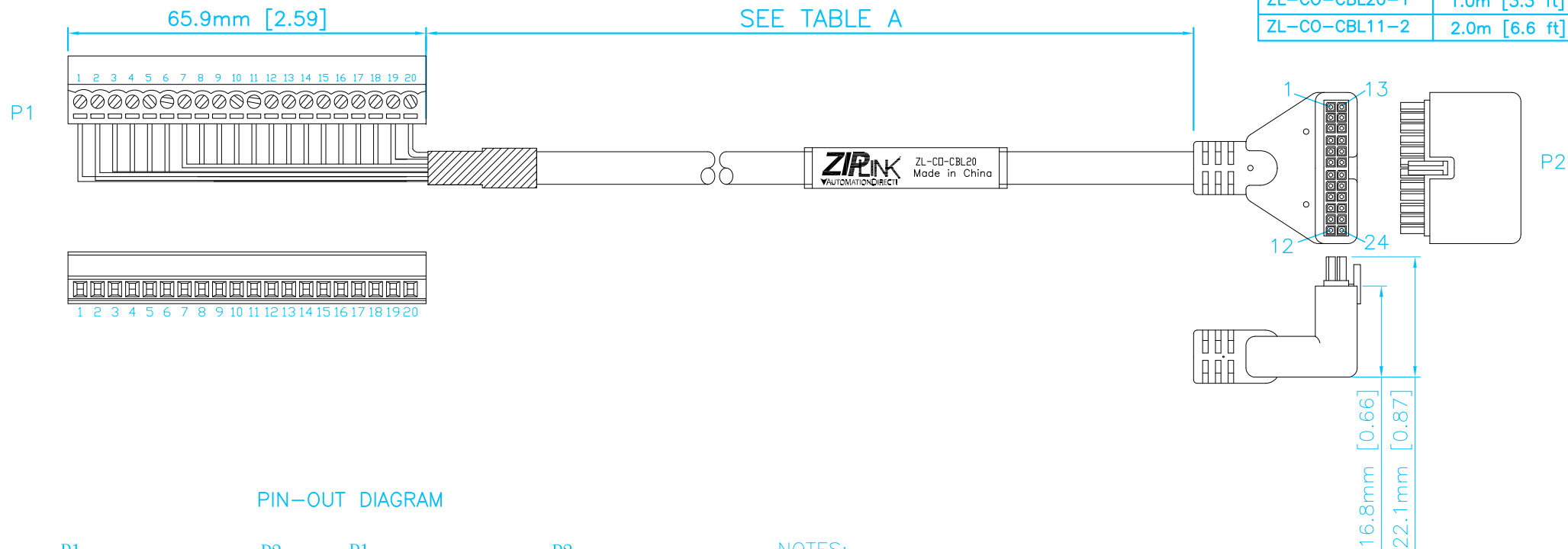

PIN-OUT DIAGRAM

P1	P2	P1	P2
1 - BLACK	1	11 - YELLOW	7
2 - BLACK/WHITE	13	12 - YELLOW/BLACK	19
3 - RED	3	13 - LIGHTGREEN	9
4 - ORANGE	4	14 - LIGHTBLUE	10
5 - GREEN	5	15 - PINK	11
6 - VIOLET	6	16 - BLUE	12
7 - BROWN	2	17 - GRAY	8
8 - BROWN/WHITE	14	18 - GRAY/BLACK	20
9 - RED/WHITE	15	19 - GREEN/BLACK	21
10 - ORANGE/WHITE	16	20 - WHITE	22
	17	21 - RED/BLACK	23
	18	22 - ORANGE/BLACK	24

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 40A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 20-pin terminal block for Click PLC AutomationDirect part # C0-16TB
- P2 CONNECTOR - 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-CO-CBL20-n	
Rev: original	Date: 07/2009
Units: mm [inches]	
Scale: .03937	
ZIPLINK Click PLC Cable	