


TABLE A

PART NO	LENGTH
ZL-SVC-CBL50	0.5m [1.6 ft]
ZL-SVC-CBL50-1	1.0m [3.3 ft]
ZL-SVC-CBL50-2	2.0m [6.6 ft]

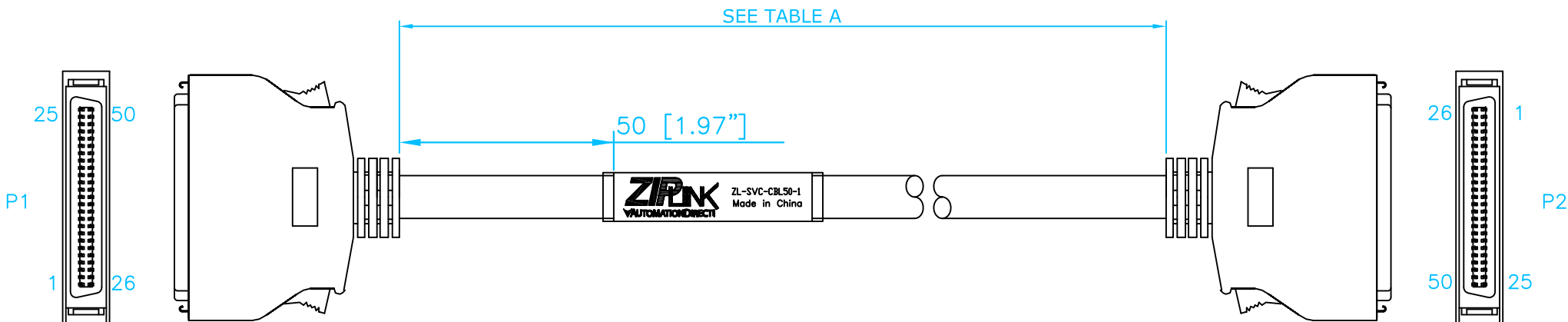

PIN-OUT DIAGRAM

P1		P2	P1		P2
1	yellow	1	14	gray/green	14
26	yellow/black	26	39	gray/yellow	39
2	red	2	15	white/yellow	15
27	red/black	27	40	white/green	40
3	brown	3	16	light green/red	16
28	brown/white	28	41	green/blue	41
4	light blue	4	17	light blue/blue	17
29	light blue/black	29	42	light blue/red	42
5	light blue/green	5	18	pink/red	18
30	light blue/yellow	30	43	pink/blue	43
6	green	6	19	gray/red	19
31	green/black	31	44	gray/blue	44
7	blue	7	20	green/white	20
32	blue/white	32	45	light green/blue	45
8	white	8	21	yellow/red	21
33	white/black	33	46	yellow/blue	46
9	pink	9	22	red/white	22
34	pink/black	34	47	red/blue	47
10	purple	10	23	white/red	23
35	purple/white	35	48	white/blue	48
11	gray	11	24	light green	24
36	gray/black	36	49	light green/black	49
12	orange	12	25	light green/yellow	25
37	orange/black	37	50	light green/green	50
13	pink/white	13			
38	pink/yellow	38			
			SHELL	BRAID+DRAIN	SHELL

NOTES:

- CABLE – 50 conductor, 28 AWG, Beige PVC jacket insulation rating 80°C (176°F), 30V
- VOLTAGE –
AC/DC rated operating voltage 24V
AC/DC maximum voltage 30V
- OPERATING TEMPERATURE – 0–60°C (32–140°F)
- P1 & P2 CONNECTOR – HPCN-50M MALE PIN/50"BLACK NICKEL-SHELL PH:1.27 SHELL-ASSEMBLY TYPE
- MINIMUM BEND RADIUS – 64mm [2.52in]

ZL-SVC-CBL50-n

Rev: C

Date: 5/2011

Units: mm [inches]

Scale: .03940

ZIPLINK SureServo Cable