


# more Of what you want in a controller

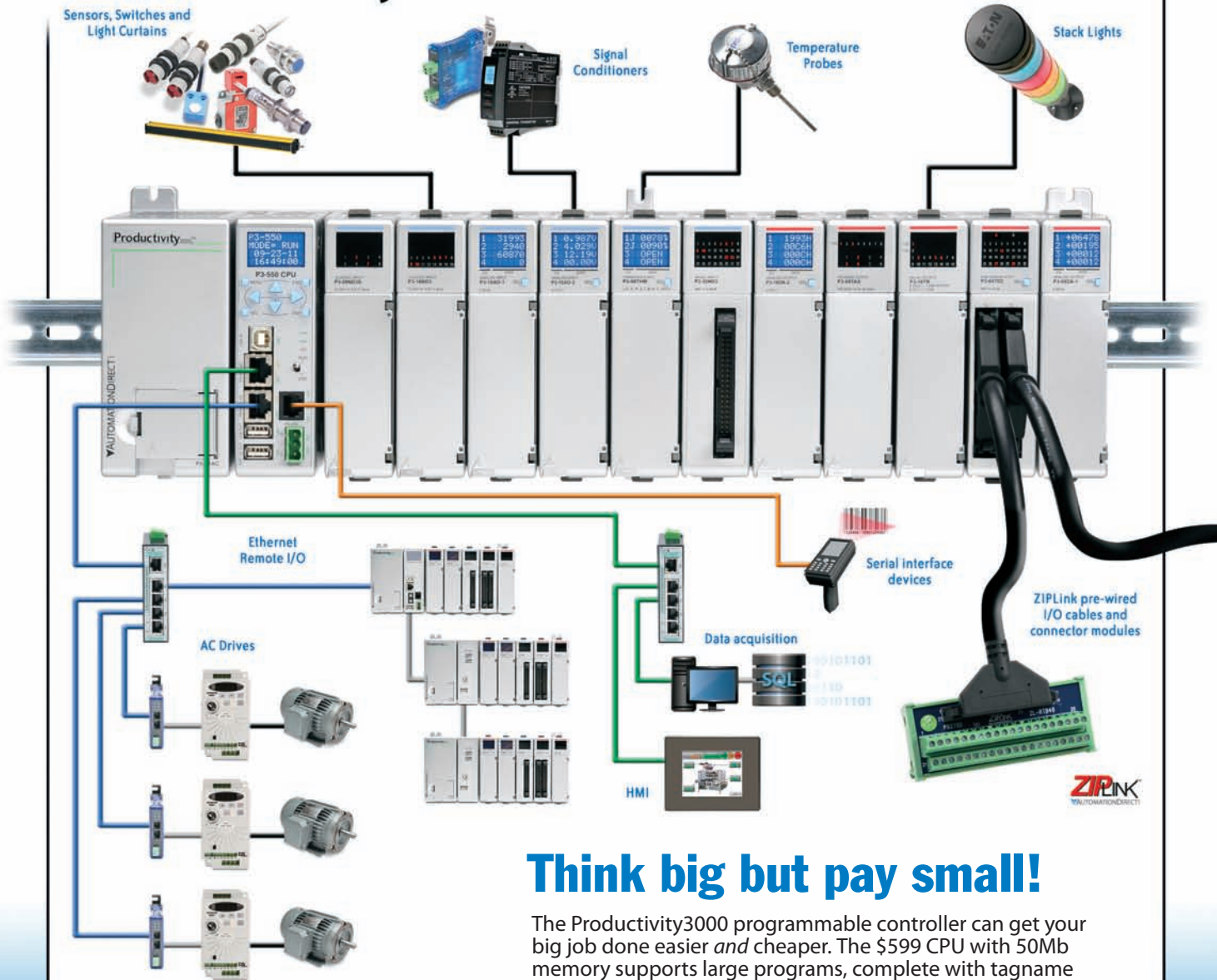

## Think big but pay small!

The Productivity3000 programmable controller can get your big job done easier *and* cheaper. The \$599 CPU with 50Mb memory supports large programs, complete with tagname database and program documentation stored onboard. The huge (100,000+) I/O capacity gives you plenty of room to plan and expand. And the CPU's seven communication ports make integrating a large system easier than you can imagine.

Download the free programming software and check it out!

Read more, watch free videos, and download the FREE software at:

[www.productivity3000.com](http://www.productivity3000.com)

**AUTOMATIONDIRECT**.com

- **USB local I/O expansion port** - supports up to four additional local I/O bases
- **Ethernet remote I/O expansion port** - supports 32 remote I/O racks and up to 64 GS series AC drives
- **High-speed Ethernet port for network of HMI** (up to 32 C-more panels), **other controllers, and enterprise system communications**
- **Two serial ports for peripheral device interface or simple controller networking**
- **USB port for data logging to removable drive, and project transfer**

