


22 mm Metal Illuminated Pilot Light

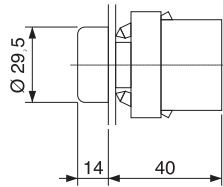

LED Illuminated Pilot Light


12 models available

- 24V and 120V with LED lamp in six colors
- Bulbs are included
- Replacement bulbs are available

Part Number	Lamp Color	Price	Description	Replacement Incandescent Bulb	Replacement LED Bulb
LED					
GCX1231-24L	Red	<--->	22 mm metal LED illuminated pilot light. 24VDC/VAC	ECX1902-5 5/pk, 80mA	ECX1911-2 2/pk, 26mA
GCX1231-120L	Red	<--->	22 mm metal LED illuminated pilot light. 120VDC/VAC	ECX1904-5 5/pk, 20mA	ECX1921-2 2/pk, 5mA
GCX1232-24L	Green	<--->	22 mm metal LED illuminated pilot light. 24VDC/VAC	ECX1902-5 5/pk, 80mA	ECX1912-2 2/pk, 26mA
GCX1232-120L	Green	<--->	22 mm metal LED illuminated pilot light. 120VDC/VAC	ECX1904-5 5/pk, 20mA	ECX1922-2 2/pk, 5mA
GCX1233-24L	Yellow	<--->	22 mm metal LED illuminated pilot light. 24VDC/VAC	ECX1902-5 5/pk, 80mA	ECX1913-2 2/pk, 26mA
GCX1233-120L	Yellow	<--->	22 mm metal LED illuminated pilot light. 120VDC/VAC	ECX1904-5 5/pk, 20mA	ECX1923-2 2/pk, 5mA
GCX1234-24L	Blue	<--->	22 mm metal LED illuminated pilot light. 24VDC/VAC	ECX1902-5 5/pk, 80mA	ECX1914-2 2/pk, 26mA
GCX1234-120L	Blue	<--->	22 mm metal LED illuminated pilot light. 120VDC/VAC	ECX1904-5 5/pk, 20mA	ECX1924-2 2/pk, 5mA
GCX1235-24L	Clear	<--->	22 mm metal LED illuminated pilot light. 24VDC/VAC	ECX1902-5 5/pk, 80mA	ECX1915-2 2/pk, 26mA
GCX1235-120L	Clear	<--->	22 mm metal LED illuminated pilot light. 120VDC/VAC	ECX1904-5 5/pk, 20mA	ECX1925-2 2/pk, 5mA
GCX1236-24L	White	<--->	22 mm metal LED illuminated pilot light. 24VDC/VAC	ECX1902-5 5/pk, 80mA	ECX1915-2 2/pk, 26mA
GCX1236-120L	White	<--->	22 mm metal LED illuminated pilot light. 120VDC/VAC	ECX1904-5 5/pk, 20mA	ECX1925-2 2/pk, 5mA

22mm Pilot Devices

Audible annunciator

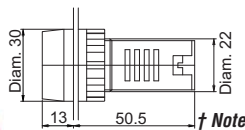

- 80 dB @ 10 cm
- 25 mA @ 24V
- Intermittent sound when energized
- IP20 before installation
- IP64 after installation


Part Number	Color	Price	Description
ECX2070-24	Black	<--->	22 mm, 25 mA audible (80dB at 10 cm) buzzer annunciator. 24VAC/DC
ECX2070-127	Black	<--->	22 mm, 25 mA audible (80dB at 10 cm) buzzer annunciator. 120VAC/DC
ECX2071-24R	Red	<--->	22 mm, 25 mA audible (80dB at 10 cm) buzzer annunciator with non-replaceable LED indicator. 24VAC/DC
ECX2071-127R	Red	<--->	22 mm, 25 mA audible (80dB at 10 cm) buzzer annunciator with non-replaceable LED indicator. 120VAC/DC

22 mm potentiometer



• IP65

Part Number	Quantity	Price	Description
ECX2300-5K	pkg. of 1	<--->	22 mm potentiometer with 5k Ω resistance, $\pm 10\%$. Nominal voltage: 250V. Rated dissipation: 2W at 25°C. Temperature range -40°C to 70°C. Black handle
ECX2300-10K	pkg. of 1	<--->	22 mm potentiometer with 10k Ω resistance, $\pm 10\%$. Nominal voltage: 250V. Rated dissipation: 2W at 25°C. Temperature range -40°C to 70°C. Black handle
ECX2640	pkg. of 1	<--->	22 mm legend plate for potentiometer with 0% to 100% marking, 50 mm square. 50 x 50 x 1mm with 24.5mm cutout.

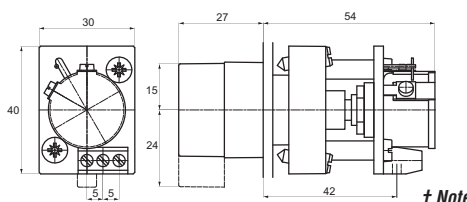

† Note: All dimensions are in millimeters.
25.4mm = 1 inch.
For example,
30 mm in inches = 30/25.4 = 1.181 inches.

Note: Find our extensive line of accessories on pages 25-42 to 25-44.