

# Marking Accessories



DN-LB (blank) shown above



DN-LAB (blank) shown on left; part of DN-LA100 on right




DN-LTA marker shown top; DN-LT60 marker shown middle; DN-LTGND shown bottom

## DN-L

**Fits terminal block types:** All except, **Screwless DINnectors**, DN-T12-A, DN-M10-A, DN-MG, and DN-TL series  
**Material:** Thermoplastic with heat embossed black print

Note:

- The marking sequence of 50 tags (i.e. 101-150) is printed 10 times in each package of 500 tags.
- The DN-L tags fit all **DINnectors** 6mm wide and wider.
- The DN-L tags fit all **DINnectors** 6mm wide and wider but will leave a gap between tags on blocks wider than 6mm.

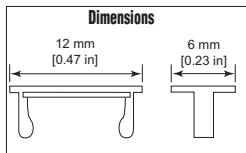



Marking Sequence	Part#	Pcs/Pkg	Price
1-50	DN-L50	500	<--->
51-100	DN-L100	500	<--->
101-150	DN-L150	500	<--->
151-200	DN-L200	500	<--->
201-250	DN-L250	500	<--->
251-300	DN-L300	500	<--->
301-350	DN-L350	500	<--->
351-400	DN-L400	500	<--->
401-450	DN-L450	500	<--->
Blank	DN-LB	500	<--->
L1, L2, L3, L, N, GND, +, -, COM, COM*	DN-LS	500	<--->

## DN-QLS

**Fits terminal block types:** Screwless DN-Q series  
**Material:** Thermoplastic with heat embossed black print. Packaged 100 labels per card, and five cards per box.

Note:

- The marking sequence (i.e. 1-100) is printed five times in each package of 500 tags.

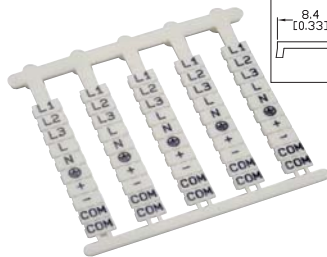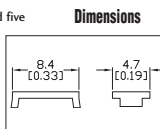


Marking Sequence	Part #	Pcs/Pkg	Price
1-100	DN-QL100	500	<--->
101-200	DN-QL200	500	<--->
201-300	DN-QL300	500	<--->
301-400	DN-QL400	500	<--->
401-500	DN-QL500	500	<--->
Blank Tags	DN-QLB	500	<--->
L1, L2, L3, L, N, +, -, COM, COM*	DN-QLS	500	<--->

## DN-LA

**Fits terminal block types:** DN-T12-A series  
**Material:** Thermoplastic with heat embossed black print

Note:

- The marking sequence (i.e. 1-100) is printed five times in each package of 500 tags.
- The DN-T12-A series is 5mm wide, so the 6mm wide DN-L tags do not fit these blocks.
- The DN-LA tags fit all **DINnectors** 5mm wide and wider but will leave a gap between tags on blocks wider than 5mm.

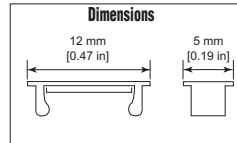


Marking Sequence	Part#	Pcs/Pkg	Price
1-100	DN-LA100	500	<--->
101-200	DN-LA200	500	<--->
201-300	DN-LA300	500	<--->
301-400	DN-LA400	500	<--->
Blank Tags	DN-LAB	500	<--->
L1, L2, L3, L, N, GND, +, -, COM, COM*	DN-LAS	500	<--->

## DN-LAT

**Fits terminal block types:** Triple level DN-TL14  
**Material:** Thermoplastic with heat embossed black print

Note:

- The marking sequence (i.e. 1-100) is printed five times in each package of 500 tags.

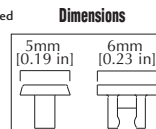


Marking Sequence	Part #	Pcs/Pkg	Price
1-100	DN-LAT100-A	500	<--->
101-200	DN-LAT200-A	500	<--->
201-300	DN-LAT300-A	500	<--->
301-400	DN-LAT400-A	500	<--->
401-500	DN-LAT500-A	500	<--->
501-600	DN-LAT600-A	500	<--->
Blank Tags	DN-LATB-A	500	<--->
L1, L2, L3, L, N, +, -, COM, COM*	DN-LATS-A	500	<--->

## DN-LT

**Fits terminal block types:** All except **Screwless** (see DN-QL series)  
**Material:** Thermoplastic with heat embossed black print

Note:

- These marking tags allow the flexibility of creating custom marking sequences on site.
- The DN-M10-A support a maximum of three digits (tags), while other **DINnectors** support up to four digits (tags)

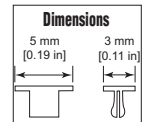

Marking Sequence	Part#	Pcs/Pkg	Price
1-5	DN-LT15	100	<--->
6-0	DN-LT60	100	<--->
1	DN-LT1	100	<--->
2	DN-LT2	100	<--->
3	DN-LT3	100	<--->
4	DN-LT4	100	<--->
5	DN-LT5	100	<--->
6	DN-LT6	100	<--->
7	DN-LT7	100	<--->
8	DN-LT8	100	<--->
9	DN-LT9	100	<--->
0	DN-LT0	100	<--->
Unprinted	DN-LTBLENK	100	<--->
A	DN-LTA	100	<--->
B	DN-LTB	100	<--->
C	DN-LTC	100	<--->
D	DN-LTD	100	<--->
E	DN-LTE	100	<--->
F	DN-LTF	100	<--->
G	DN-LTG	100	<--->
H	DN-LTH	100	<--->
I	DN-LTI	100	<--->
J	DN-LTJ	100	<--->
K	DN-LTK	100	<--->
L	DN-LTL	100	<--->
M	DN-LTM	100	<--->
N	DN-LTN	100	<--->
-	-	-	-
P	DN-LTP	100	<--->
Q	DN-LTQ	100	<--->
R	DN-LTR	100	<--->
S	DN-LTS	100	<--->
T	DN-LTT	100	<--->
U	DN-LTU	100	<--->
V	DN-LTV	100	<--->
W	DN-LTW	100	<--->
X	DN-LTX	100	<--->
Y	DN-LTY	100	<--->
Z	DN-LTZ	100	<--->
⊕	DN-LTGND	100	<--->
+	DN-LTPOS	100	<--->
-	DN-LTNEG	100	<--->
~	DN-LTAC	100	<--->
=	DN-LTDC	100	<--->

# DINnectors Accessories – Marking

## Terminal Marking Accessories



DN-EMLBL1



DN-EMLBL2




DN-EMLBL3

Part #	Description	For Use With	Pcs/Pkg	Price Each
<b>DN-EMLBL1</b>	Blank labels	DN-EMPEG1 pin protectors for DN-xEMXxx plug-in terminal blocks	100	<--->
<b>DN-EMLBL2</b>	Labels printed 1 – 12		100	<--->
<b>DN-EMLBL3</b>	Labels printed 13 – 24		100	<--->



DN-MTA marking tag adapter

### DN-MTA dimensions

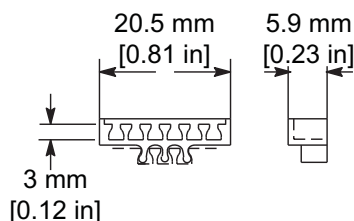

Part#	Description	Pcs/Pkg	Price Each
<b>DN-MTA</b>	Marking tag adapter holds up to six DN-LT tags	50	<--->

**Note:**  
DN-MTA adapter does not fit DN-T12-A terminal blocks.

## Marking Pen – for terminal and wire marking tags

- Permanent
- Smudge-proof
- Waterproof
- Weatherproof
- Lightfast (won't fade)
- Dries in seconds (excellent for left-handed users)
- Dry-safe (pen can be left uncapped for days without drying out)
- Low odor ink

Part#	Description	Pcs/Pkg	Price Each
<b>DN-MP</b>	Indelible black ink marking pen	1	<--->



Marking pen

## Wire Marking Accessories



DN-WMTAG1 wire tags &amp; DN-WM-x wire tag holders

Part #	Description	For Use With	Pcs/Pkg	Price Each
<b>DN-WMTAG1</b>	Wire tag – blank	all DN-WM-x wire tag holders	525	<--->
<b>DN-WM-1</b>	Wire tag holder, clear, 12 mm length, 0.051–0.118 in diameter; for 22–16 AWG wire	DN-WMTAG1	200	<--->
<b>DN-WM-2</b>	Wire tag holder, clear, 12 mm length, 0.098–0.196 in diameter; for 16–11 AWG wire		200	<--->
<b>DN-WM-3</b>	Wire tag holder, clear, 12 mm length, 0.157–0.393 in diameter; for 13–5 AWG wire		100	<--->
<b>DN-WM-4</b>	Wire tag holder, clear, 12 mm length, 0.314–0.629 in diameter; for 5 AWG wire		100	<--->

# Screwdriver Application Guide

## Application Guide

AutomationDirect also sells high-quality insulated screwdrivers. Use these tables to find the right screwdriver to use for your DINnectors or PLC terminals.

See the Tools section in this catalog for more information on these screwdrivers.



Screwdriver Application Guide							
DINnectors & PLC Terminals	Insulated Slotted Screwdrivers				Insulated Phillips Screwdrivers		6mm Hex Head
	TW-SD-VSL-1, DN-SS1	TW-SD-VSL-2, DN-SS3	TW-SD-VSL-3, DN-SS4	TW-SD-VSL-4, DN-SS5	TW-SD-VPH-1, DN-SP1	TW-SD-VPH-2, DN-SP2	
DN-D10-A		X					
DN-D10DR-A		X					
DN-D10LED1-A		X					
DN-D10X-A		X					
DN-DIS10			X				
DN-F6			X				
DN-F6L24			X				
DN-F6L110			X				
DN-F6L220			X				
DN-F10		X					
DN-F10L24		X					
DN-F10L110		X					
DN-F10L220		X					
DN-G1/0				X			
DN-G4				X			
DN-G6			X				
DN-G8			X				
DN-G10		X					
DN-KBD12	X						
DN-M10-A		X					
DN-M10B-A		X					
DN-MG10		X					
DN-T1/0				X			
DN-T1/0B				X			
DN-T3/0							X
DN-T4				X			
DN-T4B				X			
DN-T6			X				
DN-T6B			X				
DN-T8			X				
DN-T8B			X				
DN-T10-A		X					
DN-T10B-A		X					
DN-T12-A	X						
DN-T12B-A	X						
DN-TL14-A	X						
DN-TL14S-A	X						
DN-TL14SLP-A	X						
DN-TL14SLN-A	X						
D2-8IOCON					X		
D2-16IOCON	X						
D3-16IOCON					X		
D4-16IOCON						X	

**Note:** See next page for additional selections.

# Screwdrivers Application Guide (continued)



Screwdriver Application Guide Cont.							
DINnectors & PLC Terminals	Insulated Slotted Screwdrivers				Insulated Phillips Screwdrivers		Hex Head
	TW-SD-VSL-1, DN-SS1	TW-SD-VSL-2, DN-SS3	TW-SD-VSL-3, DN-SS4	TW-SD-VSL-4, DN-SS5	TW-SD-VPH-1, DN-SP1	TW-SD-VPH-2, DN-SP2	
CO-3TB	X						
CO-4TB	X						
CO-8TB	X						
CO-16TB	X						
DN-THERM1	X						
DN-THERM2	X						
DN-FE2		X					
DN-FE2L12		X					
DN-FE2L24		X					
DN-FE4		X					
DN-FE4L12		X					
DN-FE4L24		X					
DN-DIS2		X					
DN-DIS2L12		X					
DN-DIS2L24		X					
DN-DIS4		X					
DN-DIS4L12		X					
DN-DIS4L24		X					
DN-EMXM1		X					
DN-EMXDV		X					
DN-QEMXM1			X				
DN-QEMXDV			X				
DN-Q12-A		X					
DN-Q12B-A		X					
DN-Q10-A			X				
DN-Q10B-A			X				
DN-Q8-A			X				
DN-Q8B-A			X				
F0-IOCON	X						
F1-IOCON					X		
P3-RTB					X		