




Plug-In Terminal Blocks

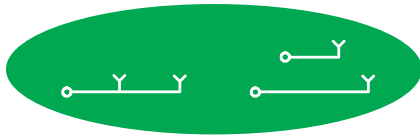


Single and double level DN-EMxx plug-in terminal blocks with screw terminals accept all DN-xxPLUG Euro plugs.

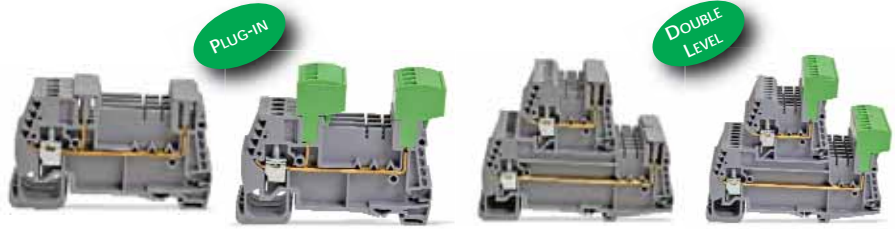

(4) DN-EMXM1 – Series: EURO XM1/2V (4) DN-EMXM1 with (2) DN-4PLUG (4) DN-EMXDV – Series: EURO XDV (4) DN-EMXDV with (2) DN-4PLUG

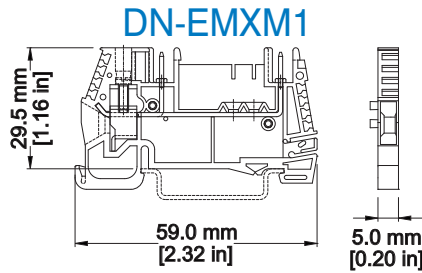


DN-EMXDV

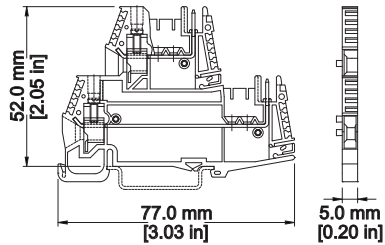

DN-xJ2Y


5.1 mm [0.20 in]

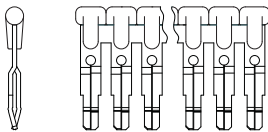

DN-J2CUT
Jumper Cutting Tool



DN-xxPLUG

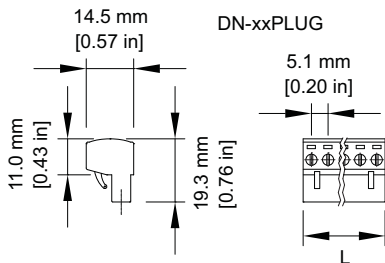

For more information on accessories, see the "DINnectors Accessories" section of this chapter.

	Part #	Pcs/Pkg	Price/Pkg	Part #	Pcs/Pkg	Price/Pkg
Gray Term Block	DN-EMXM1	32	<--->	DN-EMXDV	32	<--->
Plug-In Terminal Blocks Specifications						
Levels	single			double		
UL Approval *	300V	12A	24–12 AWG*	300V	12A	24–12 AWG*
Agency File #	UL E179129					
Wire Strip Length	0.31 in (8mm)					
Tightening Torque	4 lb-in (0.45Nm)					
Operating Temperature	Ambient air temperature: -13°F to 104°F (-25°C to 40°C) Relative humidity: 50% max at 104°F (40°C); 90% max at 68°F (20°C)					
* For copper wire only						

Accessories							
	Part #	Pcs /Pkg	Price /Pkg	Part #	Pcs /Pkg	Price /Pkg	
End Bracket	DN-EB35				50	<--->	
	DN-EB35MN				20	<--->	
	DN-EB35-A				50	<--->	
	DN-QEB35				50	<--->	
End Cover	left (open) side	DN-EMXM1EC1	25	<--->	DN-EMXDVEC1	25	<--->
	right (closed) side	DN-EMXM1EC2		<--->	DN-EMXDVEC2	25	<--->
Spacer	either side	DN-EMXM1SPA1	<--->	DN-EMXDVSPA1		<--->	
Jumpers *	2-pole	DN-2J2Y				100	<--->
	3-pole	DN-3J2Y				100	<--->
	multi-pole (24)	DN-24J2Y				5	<--->
Jumper Cutting Tool *	DN-J2CUT				1	<--->	
Pin Protector – 4-pole	DN-EMPEG1	each piece covers & protects up to 4 unused pins			16	<--->	
Marking Tags	DN-LA, DN-LT, or DN-EMBL series				500/100	various	
Angled Support Bracket	DN-ASB1	raises and tilts DIN rail for easier wiring			50	<--->	
DIN Rail (35 mm)	DN-R35S1 (7.5 mm) or DN-R35HS1 (15 mm)				10	various	
* Jumper Cutting Tool DN-J2CUT cuts EURO J 2.5 multi-pole jumpers and MAINTAINS THE INSULATION							

Accessories – Terminal Plugs							
	Part #	# Poles	Length	Ratings	Pcs /Pkg	Price /Pkg	
Plugs *	DN-2PLUG	2	L = 0.40 in [10.2 mm]	300V, 12A	200	<--->	
	DN-3PLUG	3	L = 0.60 in [15.2 mm]		14–22 AWG, CU only	200	<--->
	DN-4PLUG	4	L = 0.80 in [20.3 mm]			100	<--->
	DN-5PLUG	5	L = 1.00 in [25.4 mm]	Tightening Torque: 4.5 lb-in [0.51 N-m]		100	<--->
	DN-6PLUG	6	L = 1.20 in [30.5 mm]	Operating Temperature: -13°F to 104°F (-25°C to 40°C)	100	<--->	
	DN-7PLUG	7	L = 1.40 in [35.6 mm]		50	<--->	
	DN-8PLUG	8	L = 1.60 in [40.6 mm]		50	<--->	
	DN-9PLUG	9	L = 1.80 in [45.7 mm]	Relative humidity: 50% max at 104°F (40°C); 90% max at 68°F (20°C)	50	<--->	
	DN-10PLUG	10	L = 2.00 in [50.8 mm]		50	<--->	
	DN-11PLUG	11	L = 2.20 in [55.9 mm]		50	<--->	
	DN-12PLUG	12	L = 2.40 in [61.0 mm]	UL file #: E179129	50	<--->	
	* DN-xxPLUGs fit all DN-EMXxx & DN-QEMXxx plug-in terminal blocks						