

Marking Accessories



DN-LB (blank) shown above



DN-LAB (blank) shown on left; part of DN-LA100 on right



DN-LTA marker shown top; DN-LT60 marker shown middle; DN-LTGND shown bottom


DN-L

Fits terminal block types: All except, Screwless DINnectors, DN-T12-A, DN-M10-A, DN-MG, and DN-TL series

Material: Thermoplastic with heat embossed black print

Note:

- The marking sequence of 50 tags (i.e. 101-150) is printed 10 times in each package of 500 tags.
- The DN-L tags fit all DINnectors 6mm wide and wider.
- The DN-L tags fit all DINnectors 6mm wide and wider but will leave a gap between tags on blocks wider than 6mm.

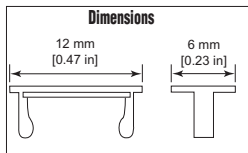


DN-LA

Fits terminal block types: DN-T12-A series

Material: Thermoplastic with heat embossed black print

Note:

- The marking sequence (i.e. 1-100) is printed five times in each package of 500 tags.
- The DN-T12-A series is 5mm wide, so the 6mm wide DN-L tags do not fit these blocks.
- The DN-LA tags fit all DINnectors 5mm wide and wider but will leave a gap between tags on blocks wider than 5mm.

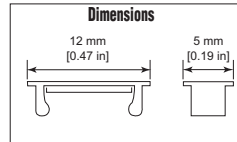


DN-LT

Fits terminal block types: All except Screwless (see DN-QL series)

Material: Thermoplastic with heat embossed black print

Note:

- These marking tags allow the flexibility of creating custom marking sequences on site.
- The DN-M10-A support a maximum of three digits (tags), while other DINnectors support up to four digits (tags)

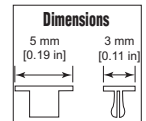

Marking Sequence	Part#	Pcs/Pkg	Price
1-50	DN-L50	500	<--->
51-100	DN-L100	500	<--->
101-150	DN-L150	500	<--->
151-200	DN-L200	500	<--->
201-250	DN-L250	500	<--->
251-300	DN-L300	500	<--->
301-350	DN-L350	500	<--->
351-400	DN-L400	500	<--->
401-450	DN-L450	500	<--->
Blank	DN-LB	500	<--->
L1, L2, L3, L, N, GND, +, -, COM, COM*	DN-LS	500	<--->

Marking Sequence	Part#	Pcs/Pkg	Price
1-100	DN-LA100	500	<--->
101-200	DN-LA200	500	<--->
201-300	DN-LA300	500	<--->
301-400	DN-LA400	500	<--->
Blank Tags	DN-LAB	500	<--->
L1, L2, L3, L, N, GND, +, -, COM, COM*	DN-LAS	500	<--->

Marking Sequence	Part#	Pcs/Pkg	Price
1-5	DN-LT15	100	<--->
6-0	DN-LT60	100	<--->
1	DN-LT1	100	<--->
2	DN-LT2	100	<--->
3	DN-LT3	100	<--->
4	DN-LT4	100	<--->
5	DN-LT5	100	<--->
6	DN-LT6	100	<--->
7	DN-LT7	100	<--->
8	DN-LT8	100	<--->
9	DN-LT9	100	<--->
0	DN-LT0	100	<--->
Unprinted	DN-LTBKLNK	100	<--->
A	DN-LTA	100	<--->
B	DN-LTB	100	<--->
C	DN-LTC	100	<--->
D	DN-LTD	100	<--->
E	DN-LTE	100	<--->
F	DN-LTF	100	<--->
G	DN-LTG	100	<--->
H	DN-LTH	100	<--->
I	DN-LTI	100	<--->
J	DN-LTJ	100	<--->
K	DN-LTK	100	<--->
L	DN-LTL	100	<--->
M	DN-LTM	100	<--->
N	DN-LTN	100	<--->
-	-	-	-
P	DN-LTP	100	<--->
Q	DN-LTQ	100	<--->
R	DN-LTR	100	<--->
S	DN-LTS	100	<--->
T	DN-LTT	100	<--->
U	DN-LTU	100	<--->
V	DN-LTV	100	<--->
W	DN-LTW	100	<--->
X	DN-LTX	100	<--->
Y	DN-LTY	100	<--->
Z	DN-LTZ	100	<--->
⊕	DN-LTGND	100	<--->
+	DN-LTPOS	100	<--->
-	DN-LTNEG	100	<--->
~	DN-LTAC	100	<--->
=	DN-LTDC	100	<--->



DN-QLS

Fits terminal block types: Screwless DN-Q series

Material: Thermoplastic with heat embossed black print. Packaged 100 labels per card, and five cards per box.

Note:

- The marking sequence (i.e. 1-100) is printed five times in each package of 500 tags.

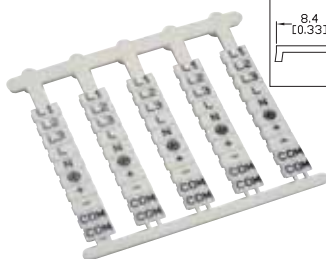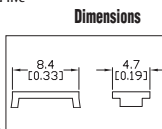

Marking Sequence	Part #	Pcs/Pkg	Price
1-100	DN-QL100	500	<--->
101-200	DN-QL200	500	<--->
201-300	DN-QL300	500	<--->
301-400	DN-QL400	500	<--->
401-500	DN-QL500	500	<--->
Blank Tags ⊕	DN-QLB	500	<--->
L1, L2, L3, L, N, ⊕, +, -, COM, COM*	DN-QLS	500	<--->


DN-LAT

Fits terminal block types: Triple level DN-TL14

Material: Thermoplastic with heat embossed black print

Note:

- The marking sequence (i.e. 1-100) is printed five times in each package of 500 tags.

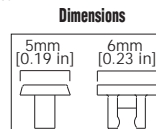

Marking Sequence	Part #	Pcs/Pkg	Price
1-100	DN-LAT100-A	500	<--->
101-200	DN-LAT200-A	500	<--->
201-300	DN-LAT300-A	500	<--->
301-400	DN-LAT400-A	500	<--->
401-500	DN-LAT500-A	500	<--->
501-600	DN-LAT600-A	500	<--->
Blank Tags	DN-LATB-A	500	<--->
L1, L2, L3, L, N, ⊕, +, -, COM, COM*	DN-LATS-A	500	<--->

DINnectors Accessories – Marking

Terminal Marking Accessories



DN-EMLBL1




DN-EMLBL2




DN-EMLBL3

Part #	Description	For Use With	Pcs/Pkg	Price Each
DN-EMLBL1	Blank labels	DN-EMPEG1 pin protectors for DN-xEMxxx plug-in terminal blocks	100	<--->
DN-EMLBL2	Labels printed 1 – 12		100	<--->
DN-EMLBL3	Labels printed 13 – 24		100	<--->

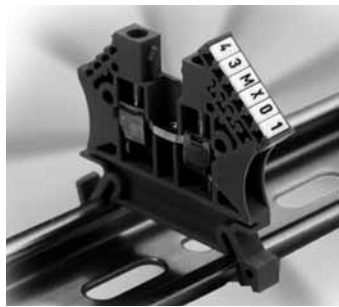

DN-MTA marking tag adapter

DN-MTA dimensions

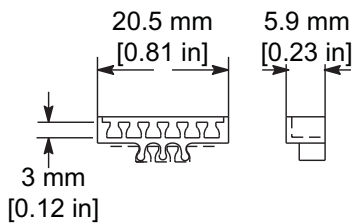

Part#	Description	Pcs/Pkg	Price Each
DN-MTA	Marking tag adapter holds up to six DN-LT tags	50	<--->

Note:
DN-MTA adapter does not fit DN-T12-A terminal blocks.

Marking Pen – for terminal and wire marking tags

- Permanent
- Smudge-proof
- Waterproof
- Weatherproof
- Lightfast (won't fade)
- Dries in seconds (excellent for left-handed users)
- Dry-safe (pen can be left uncapped for days without drying out)
- Low odor ink

Part#	Description	Pcs/Pkg	Price Each
DN-MP	Indelible black ink marking pen	1	<--->



Marking pen

Wire Marking Accessories



DN-WMTAG1 wire tags & DN-WM-x wire tag holders

Part #	Description	For Use With	Pcs/Pkg	Price Each
DN-WMTAG1	Wire tag – blank	all DN-WM-x wire tag holders	525	<--->
DN-WM-1	Wire tag holder, clear, 12 mm length, 0.051–0.118 in diameter; for 22–16 AWG wire	DN-WMTAG1	200	<--->
DN-WM-2	Wire tag holder, clear, 12 mm length, 0.098–0.196 in diameter; for 16–11 AWG wire		200	<--->
DN-WM-3	Wire tag holder, clear, 12 mm length, 0.157–0.393 in diameter; for 13–5 AWG wire		100	<--->
DN-WM-4	Wire tag holder, clear, 12 mm length, 0.314–0.629 in diameter; for 5 AWG wire		100	<--->