

Enclosure Subpanels



Enclosure Shipping Schedule		
Same day	1 - 7 days	1 -10 days
Color indicates shipping lead time in business days.		

Subpanels

Subpanels are not included with enclosures and must be purchased separately. The specifications table for each enclosure family lists the part number of the subpanel that goes with each enclosure.


Subpanels for JIC enclosures

- 14 gauge (carbon and stainless)
- Steel subpanels painted white polyester powder
- Subpanels fit the following enclosures series: B, B_CH, BN4, BN4_CH, BN4_SS, BN4_CHSS ("_" refers to dimensions).



Subpanel Part Number				Enclosure Size HxW	Subpanel Size AxB
White Steel	Price	304 Stainless	Price		
P0604	<--->	P0604SS	<--->	6x4 (152x102)	4.88x2.88 (124x73)
P0606	<--->	P0606SS	<--->	6x6 (152x152)	4.88x4.88 (124x124)
P0806	<--->	P0806SS	<--->	8x6 (203x152)	6.88x4.88 (175x124)
P0808	<--->	—		8x8 (203x203)	6.88x6.88 (175x175)
P1008	<--->	P1008SS	<--->	10x8 (254x203)	8.88x6.88 (226x175)
P1010	<--->	—		10x10 (254x254)	8.88x8.88 (226x226)
P1206	<--->	—		12x6 (305x152)	10.88x4.88 (276x124)
P1210	<--->	P1210SS	<--->	12x10 (305x254)	10.88x8.88 (276x226)
P1212	<--->	P1212SS	<--->	12x12 (305x305)	10.88x10.88 (276x276)
P1408	<--->	—		14x8 (356x203)	12.88x6.88 (327x175)
P1412	<--->	P1412SS	<--->	14x12 (356x305)	12.88x10.88 (327x276)
P1610	<--->	—		16x10 (406x254)	14.88x8.88 (378x226)
P1614	<--->	P1614SS	<--->	16x14 (406x356)	14.88x12.88 (378x327)

Note: Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawing.

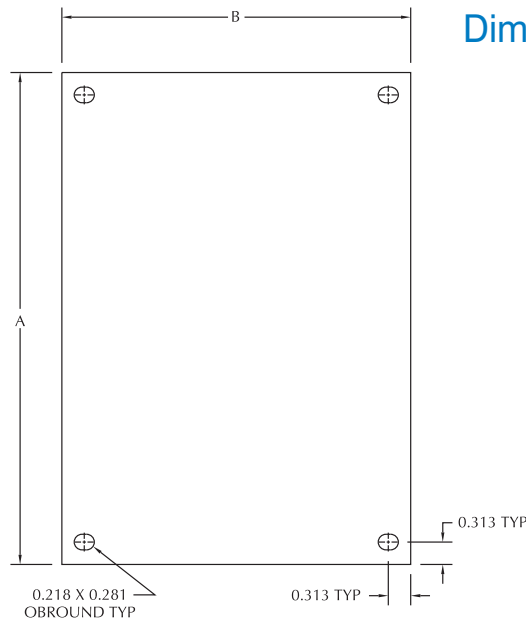

Dimensions