

CCOL and Base Series Pedestals for NEMA 12 Operator Consolets




Applications

Designed to permit floor mounting of many types of enclosures and boxes. Four column and two base sizes are available. Columns can be mounted on either base. Wiring connections can be made through the base, through the vertical column, or directly to the enclosure. Columns have flanges at each end and a gasketed access plate. Screws, oil-resistant gaskets, and box connector fitting are furnished with each column for joining an enclosure to the top of the column. A cutout must be made in the enclosure if the wires are to come through the column.



WA44CCOL shown with optional base

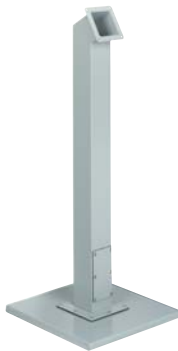

WA44BPCOL shown with optional base



Construction

Column

- Columns fabricated from 14 gauge steel with 10 gauge flanges
- Gasket, screws and box connective fittings are furnished for mounting consolet
- Columns feature gasketed access plate

Base

- 18" bases are fabricated from 10 gauge steel
- 24" bases are fabricated from 7 gauge steel
- Both bases have added reinforcing, leveling screws and holes for securing to floor

Finish

- ANSI-61 gray polyester powder inside and out over phosphatized surfaces

Listings

- UL 508, Types 12 & 13
- UL File E64791
- CSA Certified, Type 12 & 13
- CSA File LL66078
- NEMA/EEMAC Types 12 & 13

| Enclosure Shipping Schedule | | |
|--|------------|------------|
| Same day | 1 - 7 days | 1 -10 days |
| Color indicates shipping lead time in business days. | | |


| Part Number | Price | Steel Gauge | Size | Description | C | D | F | H | M | N | P |
|-------------|-------|-------------|-----------------|--------------------------|----------------|---------------|---------------|--------------|---------------|---------------|--------------|
| WA44CCOL | <---> | 14 | 4x4 (102x102) | Straight pedestal column | — | 3.75 (95) | 2.75 (70) | — | 7.25 (184) | 6.00 (152) | — |
| WA66CCOL | <---> | 14 | 6x6 (152x152) | Straight pedestal column | — | 5.75 (146) | 4.75 (121) | — | 8.00 (203) | 6.75 (171) | — |
| WA44PBCOL | <---> | 14 | 4x4 (102x102) | Angled pedestal column | — | 3.75 (95) | 2.75 (70) | — | 7.25 (184) | 6.00 (152) | — |
| WA66PBCOL | <---> | 14 | 6x6 (152x152) | Angled pedestal column | — | 5.75 (146) | 4.75 (121) | — | 8.00 (203) | 6.75 (171) | — |
| WA18SBASE | <---> | 10 | 18x18 (457x457) | Pedestal base | 18.06 (459) | — | — | 1.13 (29) | — | — | 0.47 (12) |
| WA24SBASE | <---> | 7 | 24x24 (610x610) | Pedestal base | 23.88 (606) | — | — | 1.31 (33) | — | — | 0.78 (20) |

Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.


Note: The user would normally remove the mounting feet from the enclosure if the enclosure is mounted on a pedestal.

CCOL and Base Series Pedestals for NEMA 12 Operator Consolets


Dimensions

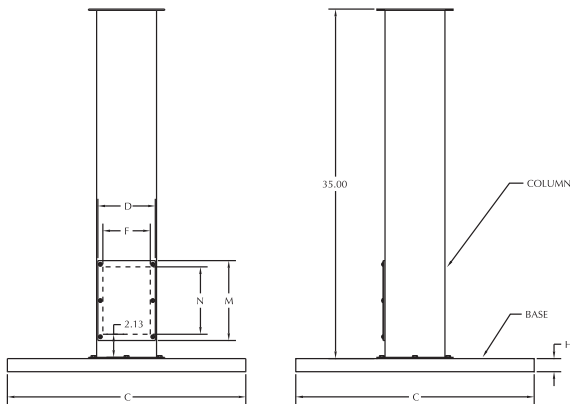


STRAIGHT PEDESTALS

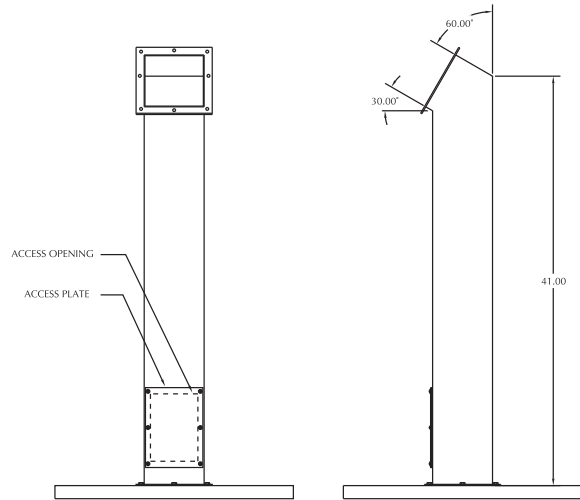


ANGLED PEDESTALS

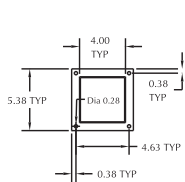


TOP FLANGE
4 X 4

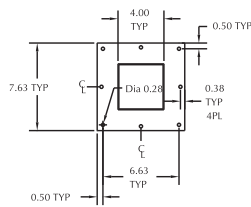

BOTTOM FLANGE
4 X 4

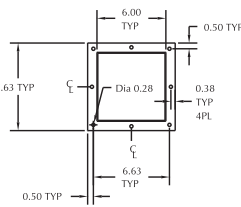

TOP AND BOTTOM FLANGES
6 X 6

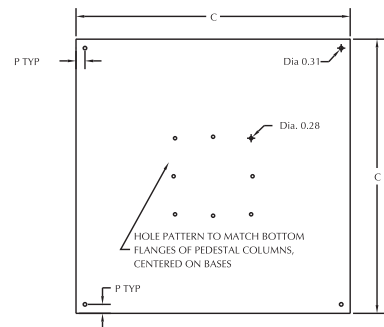

TOP VIEW OF BASES