

# NEMA 12 JIC Lift-Off Cover Wall Mount



## Applications

The Hubbell/Wiegmann B Series JIC box is a standard of the automotive industry, but also has a wide number of uses in other industries. The box incorporates a chain secured lift-off cover and is designed to safeguard components against exposure to dust, dirt, oil and water.

## Construction

- Bodies and doors fabricated from 14 gauge steel
- Continuously welded seams ground smooth, less knockouts or holes
- Lids are sealed with closed cell oil resistant neoprene gasket
- External mounting feet, top and bottom of enclosure
- Weldnuts provided for mounting optional subpanels securely on models 6"x4" and larger
- External screw clamps are quick and easy to operate
- Lift off cover design. Chain holds cover to box when cover is removed
- Grounding provisions provided

## Finish

- ANSI-61 gray polyester powder inside and out over phosphatized surfaces
- Optional subpanels are white polyester powder over phosphatized surfaces

## Listings

- UL 50, Types 12 and 13 (6x6x4 and above).
- UL 508, Types 12 and 13 (6x4x4 and smaller)
- UL Files E23553, E64791
- CSA Certified, Type 12
- CSA File LL66078
- NEMA/EEMAC Types 12 and 13
- JIC EL-1-71

Enclosure Shipping Schedule		
Same day	1 - 7 days	1 -10 days

Color indicates shipping lead time in business days.

Part Number	Price	Body/Door	Enclosure Size HxWxD	Subpanel P/N	Price	Subpanel Size AxB	Mtg CxE	Overall LxM	F	I	J	K	N	O	P	Q
<b>B040403</b>	<--->	14/14	4x4x3 (102x102x76)	<b>NA</b>	NA	NA	4.75x2 (121x51)	5.50x4.31 (140x109)	2.53 (64)	3 (76)	NA	1.38 (35)	1.50 (38)	2.59 (66)	0.56 (14)	4.31 (110)
<b>B040404</b>	<--->	14/14	4x4x4 (102x102x102)	<b>NA</b>	NA	NA	4.75x2 (121x51)	5.50x4.31 (140x109)	3.53 (90)	3 (76)	NA	1.38 (35)	1.50 (38)	3.59 (91)	0.56 (14)	4.31 (110)
<b>B060403</b>	<--->	14/14	6x4x3 (152x102x76)	<b>P0604</b>	<--->	4.88x2.88 (124x73)	6.75x2 (171x51)	7.50x4.31 (191x109)	2.53 (64)	3 (76)	0.56 (14)	1.38 (35)	1.50 (38)	2.59 (66)	0.56 (14)	6.31 (160)
<b>B060404</b>	<--->	14/14	6x4x4 (152x102x102)	<b>P0604</b>	<--->	4.88x2.88 (124x73)	6.75x2 (171x51)	7.50x4.31 (191x109)	3.53 (90)	3 (76)	0.56 (14)	1.38 (35)	1.50 (38)	3.59 (91)	0.56 (14)	6.31 (160)
<b>B060604</b>	<--->	14/14	6x6x4 (152x152x102)	<b>P0606</b>	<--->	4.88x4.88 (124x124)	6.75x2 (171x51)	7.50x6.31 (191x160)	3.53 (90)	5 (127)	0.56 (14)	2.38 (60)	1 (25)	3.59 (91)	0.56 (14)	6.31 (160)
<b>B080603</b>	<--->	14/14	8x6x3.50 (203x152x89)	<b>P0806</b>	<--->	6.88x4.88 (175x124)	8.75x4 (222x102)	9.50x6.31 (241x160)	3.03 (77)	5 (127)	0.56 (14)	2.38 (60)	1 (25)	3.09 (79)	0.56 (14)	8.31 (211)
<b>B080606</b>	<--->	14/14	8x6x6 (203x152x152)	<b>P0806</b>	<--->	6.88x4.88 (175x124)	8.75x4 (222x102)	9.50x6.31 (241x160)	5.53 (141)	5 (127)	0.56 (14)	2.38 (60)	1 (25)	5.59 (142)	0.56 (14)	8.31 (211)
<b>B080804</b>	<--->	14/14	8x8x4 (203x203x102)	<b>P0808</b>	<--->	6.88x6.88 (175x175)	8.75x6 (222x152)	9.50x8.31 (241x211)	3.53 (90)	7 (178)	0.56 (14)	1 (25)	1 (25)	3.59 (91)	0.56 (14)	8.31 (211)
<b>B100804</b>	<--->	14/14	10x8x4 (254x203x102)	<b>P1008</b>	<--->	8.88x6.88 (226x175)	10.75x6 (273x152)	11.50x8.31 (292x211)	3.53 (90)	7 (178)	0.56 (14)	1 (25)	1 (25)	3.59 (91)	0.56 (14)	10.31 (262)
<b>B100806</b>	<--->	14/14	10x8x6 (254x203x152)	<b>P1008</b>	<--->	8.88x6.88 (226x175)	10.75x6 (273x152)	11.50x8.31 (292x211)	5.53 (141)	7 (178)	0.56 (14)	1 (25)	1 (25)	5.59 (142)	0.56 (14)	10.31 (262)


Note: Subpanels must be ordered separately. Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.

# NEMA 12 JIC Lift-Off Cover Wall Mount

Part Number	Price	Body/Door	Enclosure Size HxWxD	Subpanel P/N	Price	Subpanel Size AxB	Mtg CxE	Overall LxM	F	I	J	K	N	O	P	Q
<b>B121005</b>	<--->	14/14	12x10x5 (305x254x127)	<b>P1210</b>	<--->	10.88x8.88 (276x226)	12.75x8 (324x203)	13.50x10.31 (343x262)	4.53 (115)	9 (229)	0.56 (14)	1 (25)	1 (25)	4.59 (117)	0.56 (14)	12.31 (313)
<b>B121206</b>	<--->	14/14	12x12x6 (305x305x152)	<b>P1212</b>	<--->	10.88x10.88 (276x276)	12.75x10 (324x254)	13.50x12.31 (343x313)	5.53 (141)	11 (279)	0.56 (14)	1 (25)	1 (25)	5.59 (142)	0.56 (14)	12.31 (313)
<b>B141206</b>	<--->	14/14	14x12x6 (356x305x152)	<b>P1412</b>	<--->	12.88x10.88 (327x276)	14.75x10 (375x254)	15.50x12.31 (394x313)	5.53 (141)	11 (279)	0.56 (14)	1 (25)	1 (25)	5.59 (142)	0.56 (14)	14.31 (364)
<b>B161406</b>	<--->	14/14	16x14x6 (406x356x152)	<b>P1614</b>	<--->	14.88x12.88 (378x327)	16.75x12 (425x305)	17.50x14.31 (445x363)	5.53 (141)	13 (330)	0.56 (14)	1 (25)	1 (25)	5.59 (142)	0.56 (14)	16.31 (414)

Note: Subpanels must be ordered separately. Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.

## Dimensions

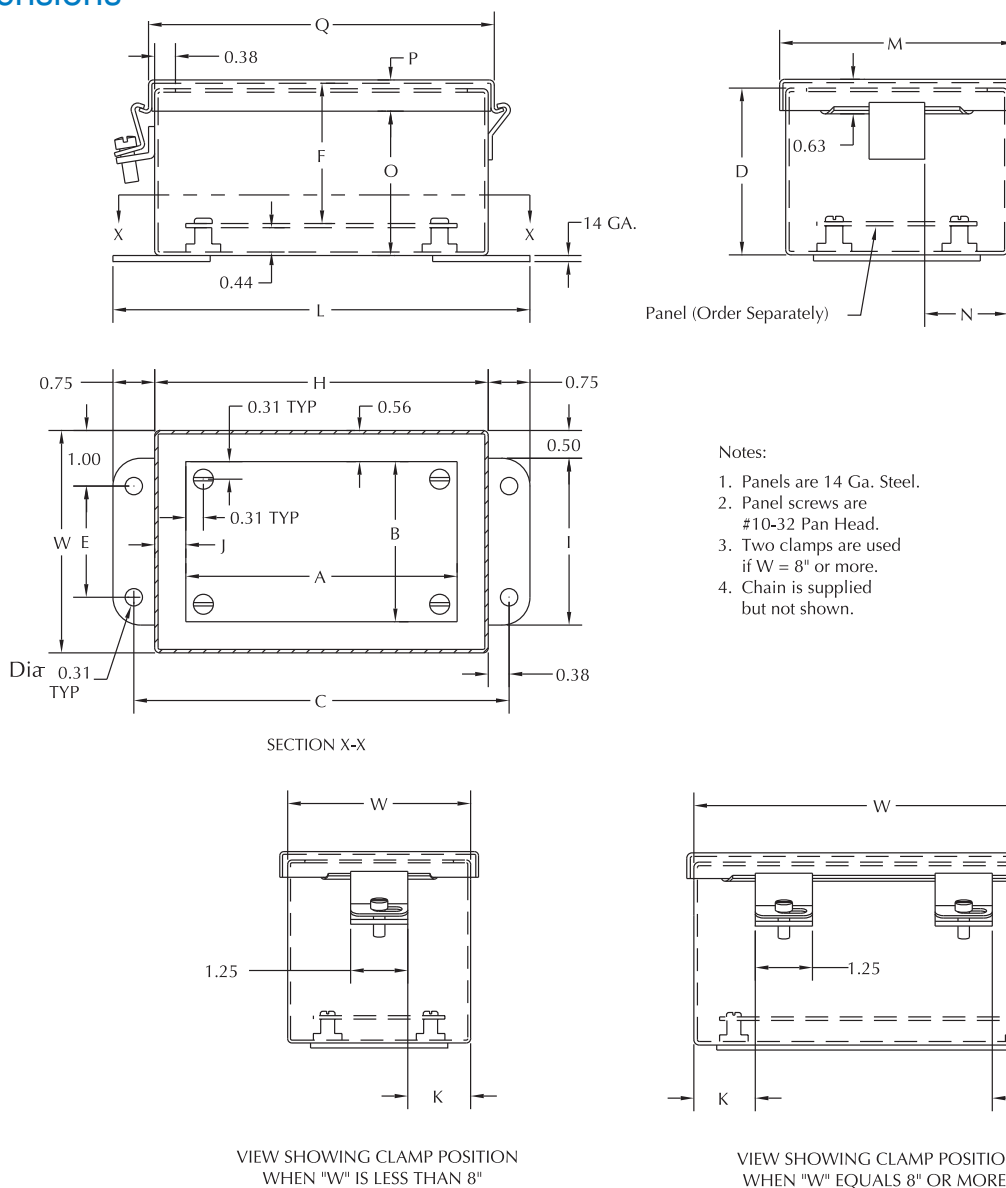

### Notes:

1. Panels are 14 Ga. Steel.
2. Panel screws are #10-32 Pan Head.
3. Two clamps are used if  $W = 8''$  or more.
4. Chain is supplied but not shown.