

# PBYX Series 30.5 mm Pushbutton NEMA 12 Wall Mount



## Applications

Designed to hold 30.5mm oil-tight push-buttons, switches and pilot lights with extra size to allow 2.5" between centers of push-button holes. Provides protection from dirt, dust, oil and water.

## Construction

- Fabricated from 14 gauge steel
- Closed cell oil-resistant neoprene gasket
- Continuously welded seams ground smooth
- Cover held in place by continuous hinge
- Subpanel included with enclosure
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Grounding provisions provided

## Finish

- ANSI-61 gray polyester powder inside and out over phosphatized surfaces
- Included subpanels are white polyester powder over phosphatized surfaces

## Listings

- UL 508, Types 12 & 13
- UL File E64791
- CSA Certified, Type 12 & 13
- CSA File LL66078
- NEMA/EEMAC Types 12 & 13
- JIC EL-1-71

### Enclosure Shipping Schedule

Same day

1 - 7 days

1 -10 days




Color indicates shipping lead time in business days.

Part Number	Price	Body/ Door	Size HxWxD	Mounting CxE	Subpanel AxB	F	G
<b>PBYX4S</b>	<--->	14 /14	8.5x7.5x6 (216x191x152)	9x6.5 (229x165)	6.5x5.5 (165x140)	7.25 (184)	4.78 (121)
<b>PBYX6</b>	<--->	14 /14	11x7.5x6 (279x191x152)	11.5x6.5 (292x165)	9x5.5 (229x140)	7.25 (184)	4.78 (121)
<b>PBYX9</b>	<--->	14 /14	11x10x6 (279x254x152)	11.5x9 (292x229)	9x8 (229x203)	9.75 (248)	4.78 (121)
<b>PBYX12</b>	<--->	14 /14	13.5x10x6 (343x254x152)	14x9 (356x229)	11.5x8 (292x203)	9.75 (248)	4.78 (121)
<b>PBYX16</b>	<--->	14 /14	13.5x12.5x6 (343x318x152)	14x11.5 (356x292)	11.5x10.5 (292x267)	12.25 (311)	4.78 (121)
<b>PBYX20</b>	<--->	14 /14	16x12.5x6 (406x318x152)	16.5x11.5 (419x292)	14x10.5 (356x267)	12.25 (311)	4.78 (121)
<b>PBYX25</b>	<--->	14 /14	16x15x6 (406x381x152)	16.5x14 (419x356)	14x13 (356x330)	14.75 (375)	4.78 (121)
<b>PBYX30</b>	<--->	14 /14	18.5x15x6 (470x381x152)	19x14 (483x356)	16.5x13 (419x330)	14.75 (375)	4.78 (121)
<b>PBYX36</b>	<--->	14 /14	18.5x17.5x6 (470x445x152)	19x16.5 (483x419)	16.5x15.5 (419x394)	17.25 (438)	4.78 (121)
<b>PBYX42</b>	<--->	14 /14	21x17.5x6 (533x445x152)	21.5x16.5 (546x419)	19x15.5 (483x394)	17.25 (438)	4.78 (121)

Note: Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.

# PBYX Series 30.5 mm Pushbutton NEMA 12 Wall Mount

## Dimensions

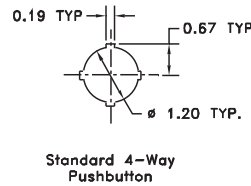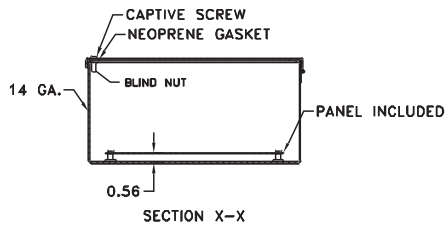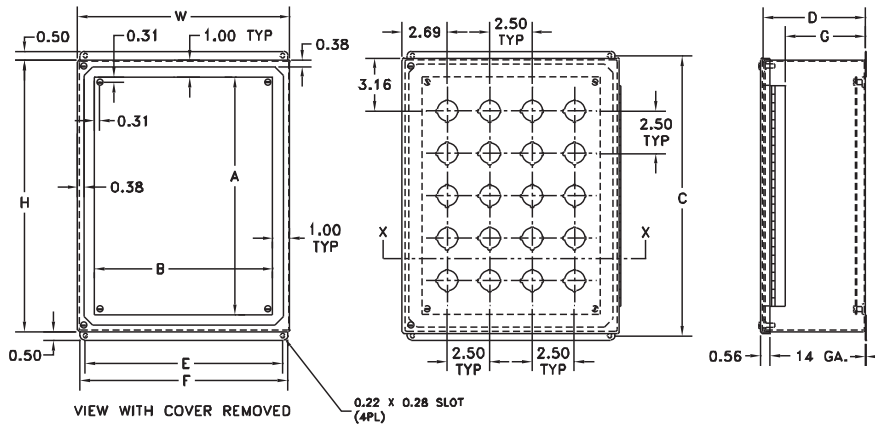

### PBYX Hole Arrangements

