



NITRA pneumatic quick-disconnect hose couplings allow easy changing of tools or hose connections. Couplers and plugs are sold separately. Industrial Interchange, ARO210 and Trufplate plugs are available in steel and chrome-plated steel. Couplers are available in Industrial Interchange manual or automatic and universal automatic. Safety couplers bleed off air pressure downstream before disconnecting.

Features

- Plugs and couplers for 1/4 and 3/8 inch hose sizes
- Male and female NPT threaded
- Thread sealant supplied on all male fittings
- Maximum pressure = 250 psi, including safety coupler fittings



HC14-38F-A



HC14-38F-B



HC14-14M-C

NITRA™ Quick-Disconnect 1/4 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HC14-14F-A	<--->	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
HC14-38F-A	<--->	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
HC14-14M-A	<--->	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
HC14-38M-A	<--->	Quick-disconnect coupler, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
HC14-14F-B	<--->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
HC14-38F-B	<--->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
HC14-14M-B	<--->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
HC14-38M-B	<--->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
HC14-14F-C	<--->	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
HC14-38F-C	<--->	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
HC14-14M-C	<--->	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
HC14-38M-C	<--->	Quick-disconnect automatic coupler, universal, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2



HCP14-14F-J



HCP14-14M-K



HCP14-14M-L



HCP14-14F-M

NITRA™ Quick-Disconnect 1/4 in. I.D. Plug Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HCP14-14F-J	<-->	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP14-38F-J	<-->	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP14-14M-J	<-->	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP14-38M-J	<-->	Quick-disconnect plug, industrial interchange, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
HCP14-14F-K	<-->	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP14-14M-K	<-->	Quick-disconnect plug, ARO 210, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP14-14F-L	<-->	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP14-38F-L	<-->	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP14-14M-L	<-->	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP14-38M-L	<-->	Quick-disconnect plug, Truflate, steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
HCP14-14F-M	<-->	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP14-38F-M	<-->	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP14-14M-M	<-->	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP14-38M-M	<-->	Quick-disconnect plug, industrial interchange, chrome plated steel, 1/4 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1



HC38-14F-A



HC38-14M-A



HC38-14M-B

NITRA™ Quick-Disconnect 3/8 in. I.D. Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HC38-14F-A	<-->	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.3
HC38-38F-A	<-->	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.3
HC38-12F-A	<-->	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.3
HC38-14M-A	<-->	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.3
HC38-38M-A	<-->	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.3
HC38-12M-A	<-->	Quick-disconnect coupler, industrial interchange, steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.3
HC38-14F-B	<-->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.2
HC38-38F-B	<-->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.2
HC38-12F-B	<-->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.2
HC38-14M-B	<-->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.2
HC38-38M-B	<-->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.2
HC38-12M-B	<-->	Quick-disconnect automatic coupler, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.2

Quick-Disconnect Fittings

NITRA™ Quick-Disconnect 3/8 in. I.D. Plug Fittings Cont'd				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HCP38-14F-J	<--->	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP38-38F-J	<--->	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP38-14M-J	<--->	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP38-38M-J	<--->	Quick-disconnect plug, industrial interchange, steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
HCP38-14F-M	<--->	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.1
HCP38-38F-M	<--->	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch female NPT threaded connection	1	0.1
HCP38-12F-M	<--->	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch female NPT threaded connection	1	0.2
HCP38-14M-M	<--->	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.1
HCP38-38M-M	<--->	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 3/8 inch male NPT threaded connection	1	0.1
HCP38-12M-M	<--->	Quick-disconnect plug, industrial interchange, chrome plated steel, 3/8 inch inside diameter with 1/2 inch male NPT threaded connection	1	0.1



HCP38-14M-J



HCP38-14F-M

NITRA™ Quick-Disconnect 1/4 in. I.D. Safety Coupler Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HC14-14M-D	<--->	Quick-disconnect automatic safety coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch male NPT threaded connection	1	0.3
HC14-14F-D	<--->	Quick-disconnect automatic safety coupler, universal, chrome plated steel, 1/4 inch inside diameter with 1/4 inch female NPT threaded connection	1	0.3




HC14-14M-D

Quick-Disconnect Swivel Fittings

Features

- Two independent-rotation points allow a full 360° circular rotation and 45° angled rotation for better swivel action vs. traditional swivel fittings
- Prevents kinking of and strain on the supply line
- Lightweight, streamlined design
- Chrome-plated steel construction for long service life
- Thread sealant supplied on all male fittings
- Maximum pressure = 145 psi

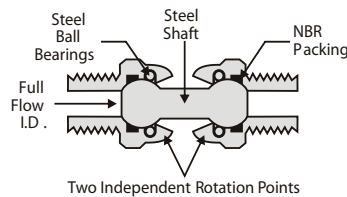

45° Swivel Design



HS14F-14M

NITRA™ 1/4 in. NPT Swivel Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HS14F-14M	<--->	Swivel fitting, chrome plated steel, 1/4 inch female NPT and 1/4 inch male NPT threaded connections	1	0.2



HSP38-14M-S

NITRA™ Quick-Disconnect Plug to NPT Swivel Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
HSP14-14M-S	<--->	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch industrial interchange plug and 1/4 inch male NPT threaded connection	1	0.2
HSP38-14M-S	<--->	Quick-disconnect swivel fitting, chrome plated steel, 3/8 inch industrial interchange plug and 1/4 inch male NPT threaded connection	1	0.2
HSP38-38M-S	<--->	Quick-disconnect swivel fitting, chrome plated steel, 3/8 inch industrial interchange plug and 3/8 inch male NPT threaded connection	1	0.2
HSP14-14M-T	<--->	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch ARO 210 plug and 1/4 inch male NPT threaded connection	1	0.1
HSP14-14M-U	<--->	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch Trufflate plug and 1/4 inch male NPT threaded connection	1	0.1