


# Quick-Disconnect Swivel Fittings

## Features

- Two independent-rotation points allow a full 360° circular rotation and 45° angled rotation for better swivel action vs. traditional swivel fittings
- Prevents kinking of and strain on the supply line
- Lightweight, streamlined design
- Chrome-plated steel construction for long service life
- Thread sealant supplied on all male fittings
- Maximum pressure = 145 psi

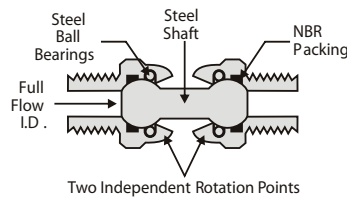

45° Swivel Design



HS14F-14M

| NITRA™ 1/4 in. NPT Swivel Fittings |       |   |               |              |
|------------------------------------|-------|---|---------------|--------------|
| Part No.                           | Price | Description   | Parts Per Pkg | Weight (lbs) |
| HS14F-14M                          | <-->  | Swivel fitting, chrome plated steel, 1/4 inch female NPT and 1/4 inch male NPT threaded connections | 1             | 0.2          |



HSP38-14M-S

| NITRA™ Quick-Disconnect Plug to NPT Swivel Fittings |       |  |               |              |
|---|-------|--|---------------|--------------|
| Part No.  | Price | Description  | Parts Per Pkg | Weight (lbs) |
| HSP14-14M-S   | <-->  | Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch industrial interchange plug and 1/4 inch male NPT threaded connection | 1             | 0.2          |
| HSP38-14M-S   | <-->  | Quick-disconnect swivel fitting, chrome plated steel, 3/8 inch industrial interchange plug and 1/4 inch male NPT threaded connection | 1             | 0.2          |
| HSP38-38M-S   | <-->  | Quick-disconnect swivel fitting, chrome plated steel, 3/8 inch industrial interchange plug and 3/8 inch male NPT threaded connection | 1             | 0.2          |
| HSP14-14M-T   | <-->  | Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch ARO 210 plug and 1/4 inch male NPT threaded connection                | 1             | 0.1          |
| HSP14-14M-U   | <-->  | Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch Trufflate plug and 1/4 inch male NPT threaded connection              | 1             | 0.1          |