


Pneumatic Push-to-Connect Fittings



NITRA pneumatic push-to-connect union Y fitting with thermoplastic (PBT) body and stainless steel tube gripping claws. For use with polyurethane or nylon tubing. Five fittings per package.

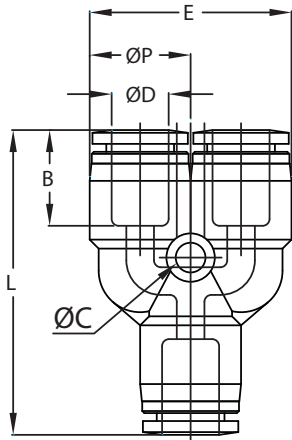


Inch Fitting



Metric Fitting

NITRA™ Union Y											
Inch Sizes - dimensions in inches (in)											
Part No.	Price	Size	ØD	ØP	L	E	ØC	B	Orifice	Package Weight (lbs)	Qty. per pack
UY532	<-->	5/32 in. [4 mm]	5/32	0.41	1.43	0.83	0.13	0.63	0.10	0.1	5
UY14	<-->	1/4 in.	1/4	0.51	1.57	1.02	0.13	0.70	0.16	0.1	5
UY38	<-->	3/8 in.	3/8	0.69	1.85	1.38	0.18	0.78	0.31	0.4	5
UY12	<-->	1/2 in.	1/2	0.83	2.16	1.65	0.18	0.90	0.41	0.4	5
Metric Sizes - dimensions in millimeters (mm)											
UY6M	<-->	6 mm	6	13.0	39.3	26.0	3.3	17.6	5.2	0.2	5
UY8M	<-->	8 mm	8	14.6	44.1	29.2	4.3	19.0	6.8	0.2	5
UY10M	<-->	10 mm	10	17.5	47.1	35.0	4.5	19.8	8.0	0.4	5
UY12M	<-->	12 mm	12	21.0	54.1	42.0	4.5	22.7	10.3	0.4	5

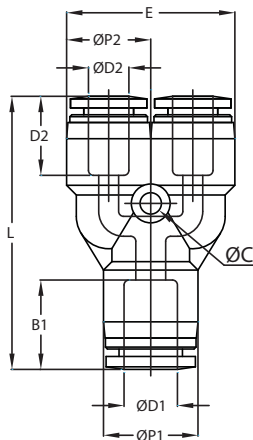

NITRA pneumatic push-to-connect union reducer Y fitting with thermoplastic (PBT) body and stainless steel tube gripping claws. For use with polyurethane or nylon tubing. Five fittings per package.



Inch Fitting



Metric Fitting

NITRA™ Union Reducer Y														
Inch Sizes - dimensions in inches (in.)														
Part No.	Price	Size	ØD1	ØD2	ØP1	ØP2	L	E	ØC	B1	B2	Orifice	Package Weight (lbs)	Qty. per pack
URY14-532	<-->	1/4 in. x 5/32 in.	1/4	5/32	0.51	10.5	38.0	0.83	0.13	0.70	0.63	0.13	0.1	5
URY38-14	<-->	3/8 in. x 1/4 in.	3/8	1/4	0.69	13.0	1.70	1.02	0.13	0.78	0.70	0.20	0.2	5
URY12-38	<-->	1/2 in. x 3/8 in.	1/2	3/8	0.83	17.5	2.00	1.38	0.18	0.90	0.78	0.28	0.3	5
Metric Sizes - dimensions in millimeters (mm)														
URY6M-4M	<-->	6 mm x 4 mm	6	4	13.0	10.5	37.8	21.0	3.3	17.6	16.1	3.4	0.1	5
URY8M-6M	<-->	8 mm x 6 mm	8	6	14.6	13.0	42.2	26.0	3.3	19.0	17.6	5.4	0.2	5
URY10M-8M	<-->	10 mm x 8 mm	10	8	17.5	14.6	44.8	29.2	4.3	19.7	19.0	7.0	0.3	5
URY12M-10M	<-->	12 mm x 10 mm	12	10	21.0	17.5	50.6	35.0	4.5	22.7	19.8	8.0	0.3	5