


DATASHEET

M12 Female Leads    IDEM

Part 140101 - 5m

Part 140102 - 10m

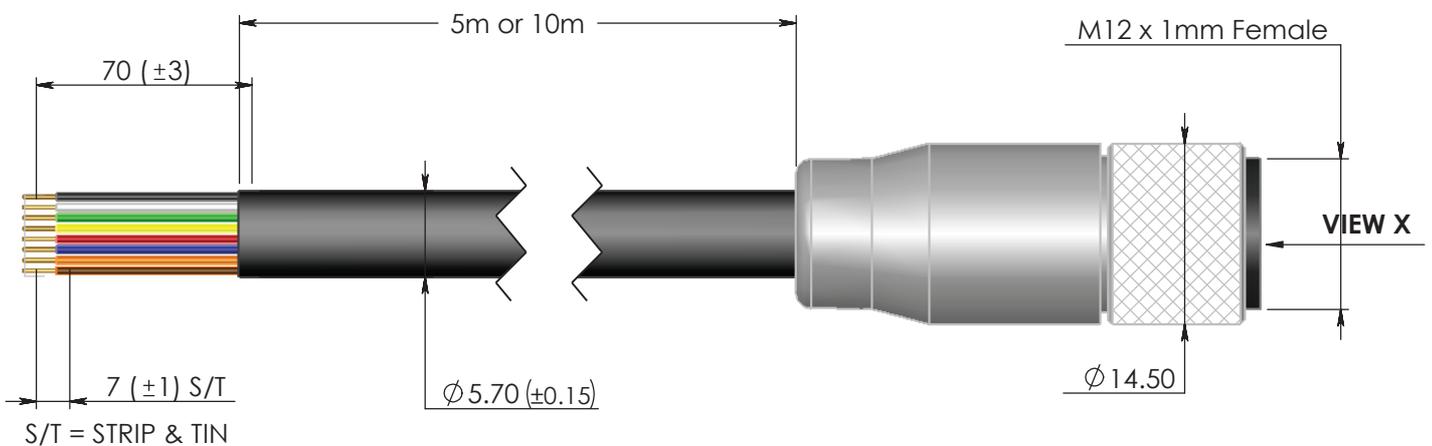

SPECIFICATION :

OPERATING TEMPERATURE RANGE : 105°C

EACH CORE 22 STRANDS OF Ø0.12mm , BARE COPPER

INNER INSULATION (CORE) DIAMETER: Ø 1.35 (±0.1)mm

OUTER SHEATH (JACKET) COLOUR : BLACK (PRINTED)

OUTER INSULATION : PVC

INNER INSULATION : PVC

NUMBER OF CORES : 8 CORES (24 AWG) UL STYLE 2517

RATED VOLTAGE / CURRENT : 250V / 3A

